




2500.00

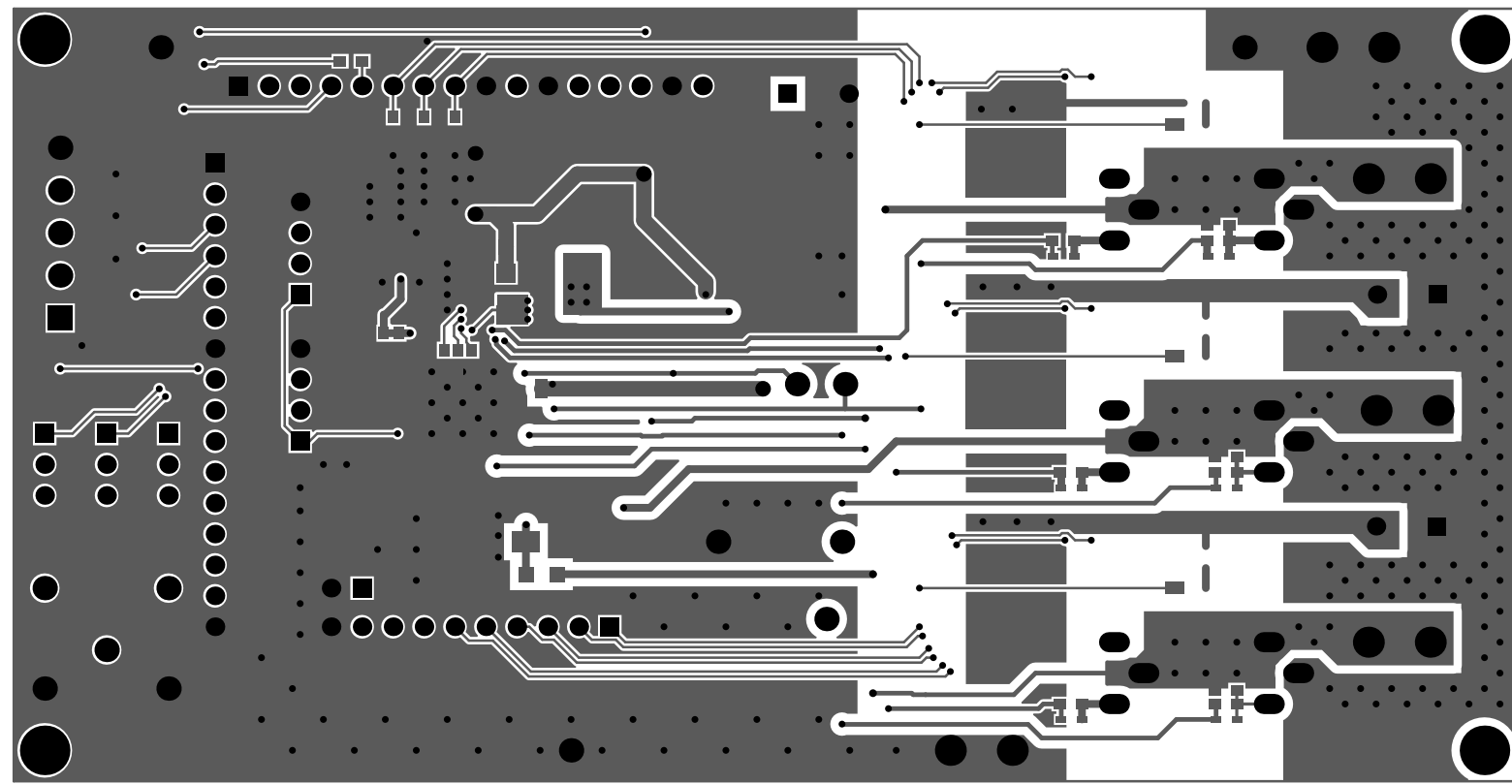


4850.00

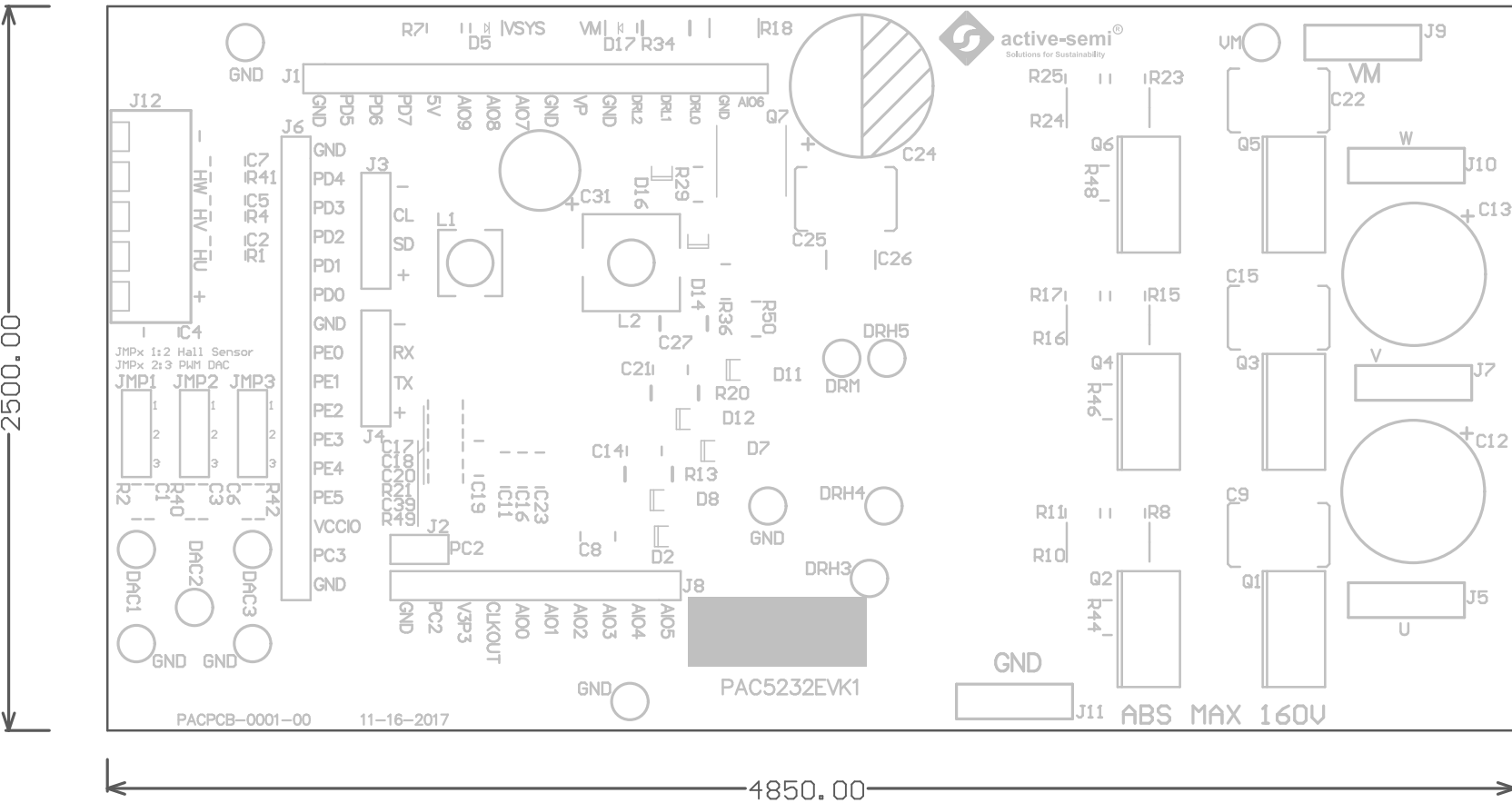


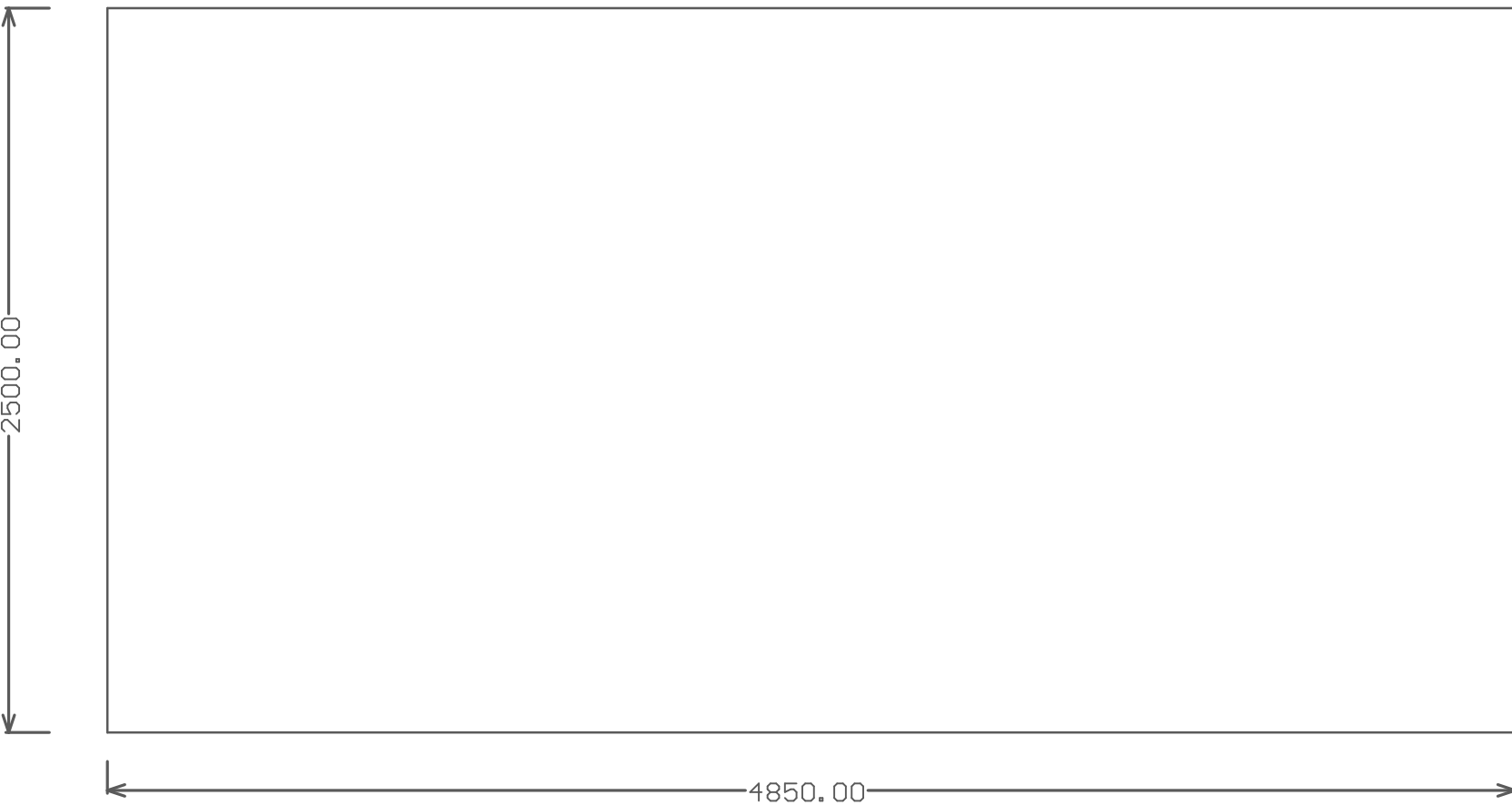


2500.00

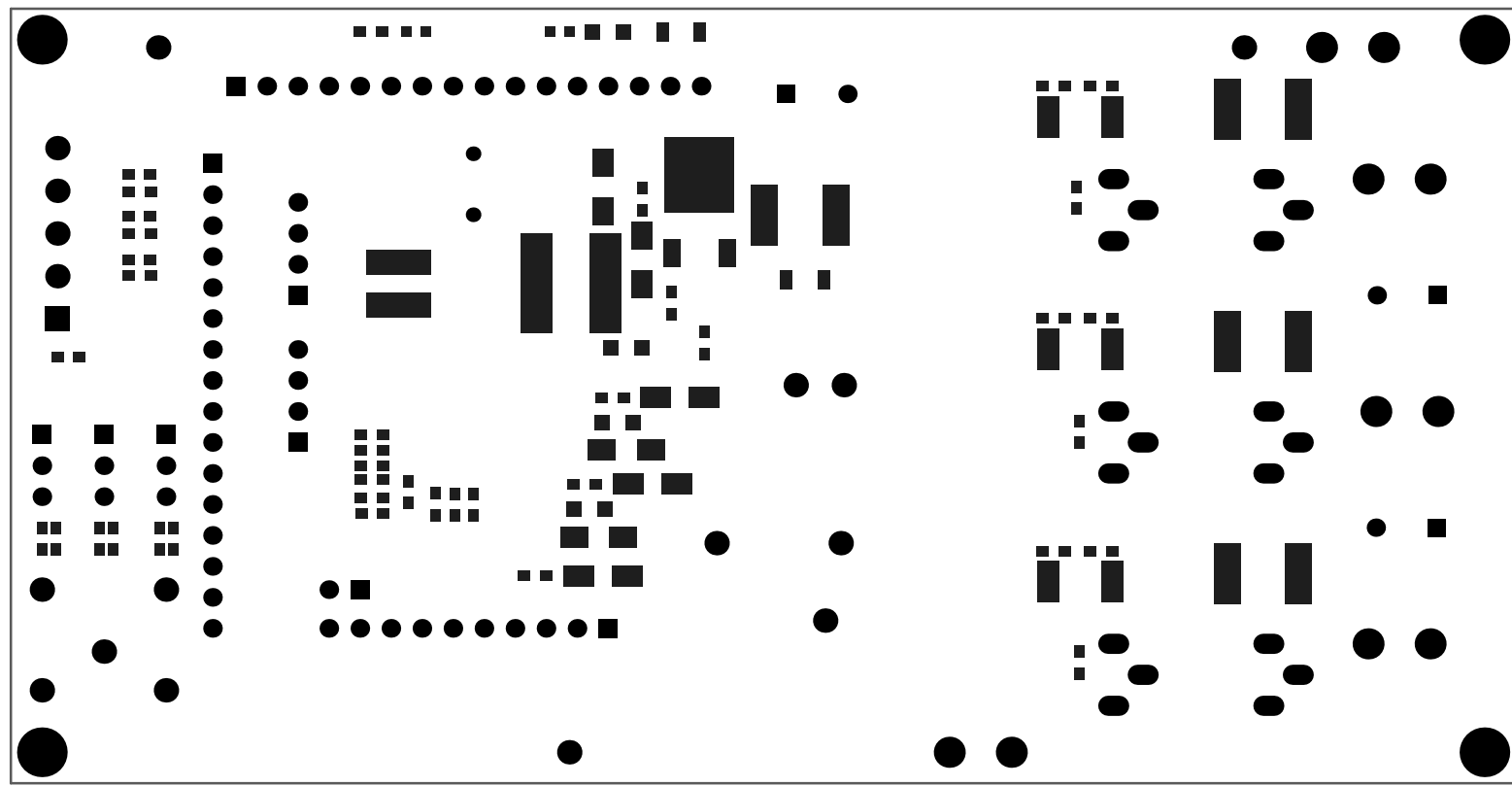


4850.00

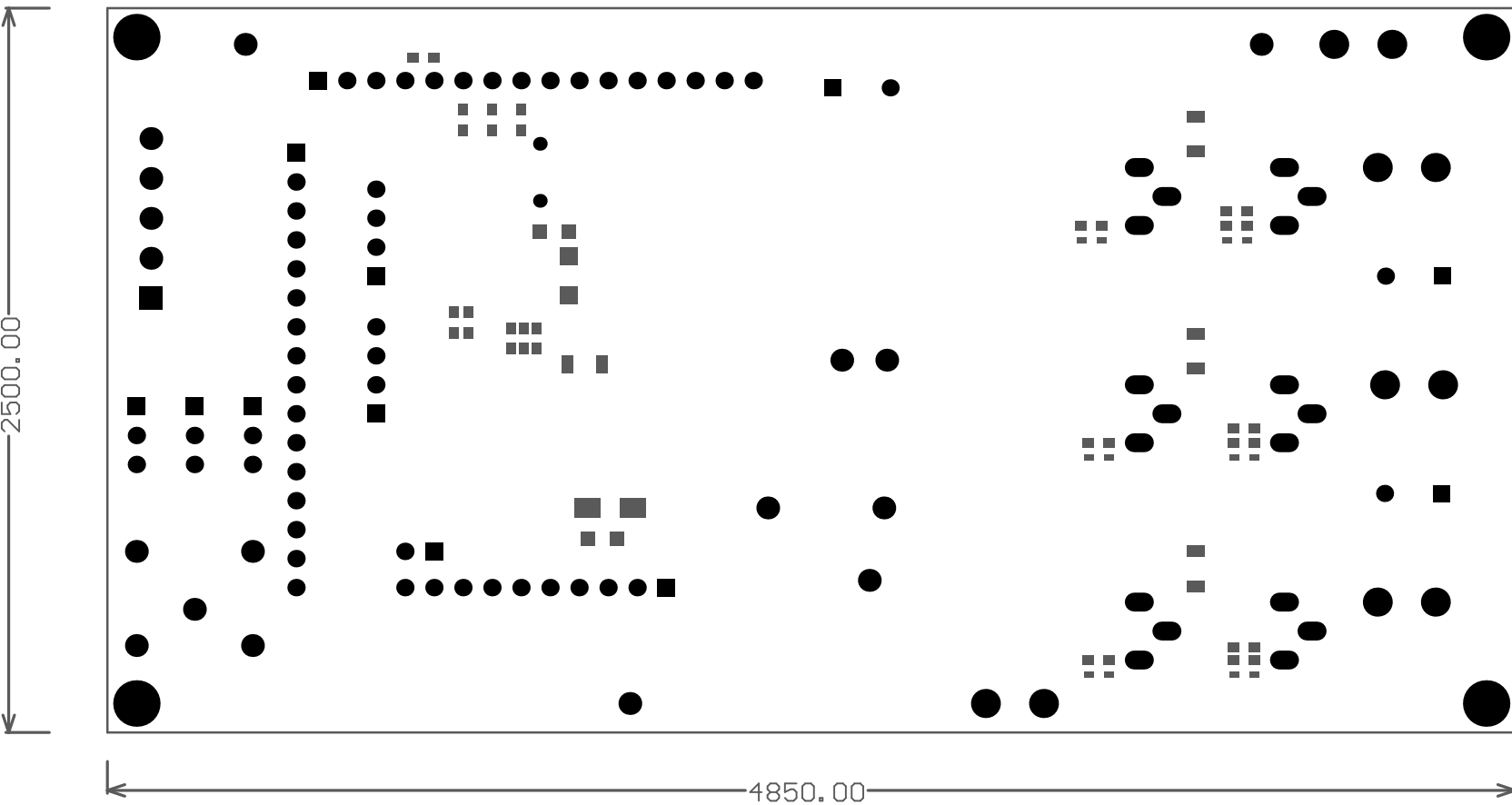

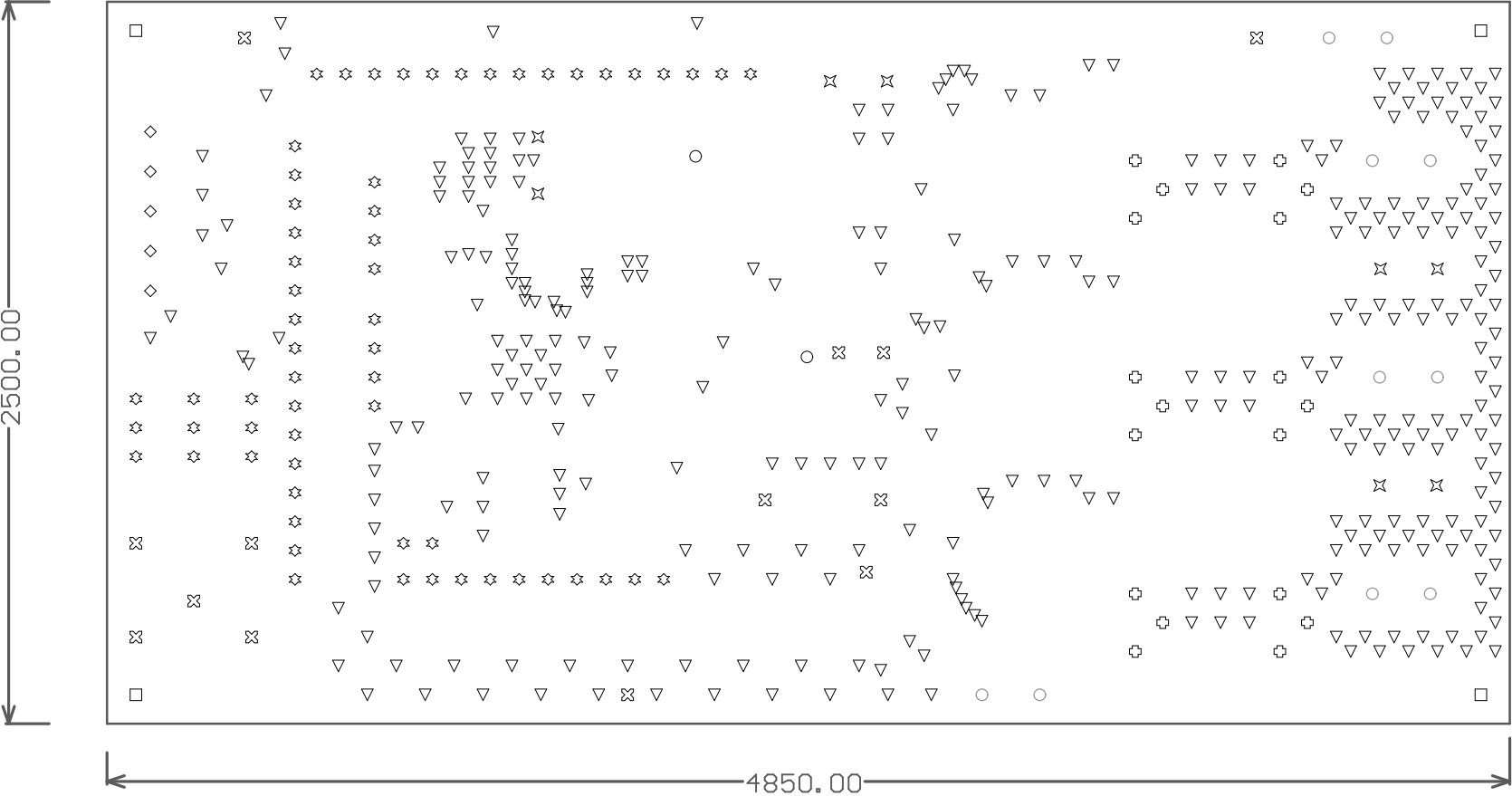

| Symbol | Hit Count | Tool Size | Plated | Hole Type |
|-----------|-----------|-------------------|--------|-----------|
| ▽ | 329 | 12mil (0.305mm) | PTH | Round |
| ◇ | 2 | 25mil (0.635mm) | PTH | Round |
| ⊠ | 8 | 27.559mil (0.7mm) | PTH | Round |
| ○ | 61 | 36mil (0.914mm) | PTH | Round |
| ○ | 18 | 40mil (1.016mm) | PTH | Round |
| ◇ | 5 | 47.244mil (1.2mm) | PTH | Round |
| ○ | 10 | 55.118mil (1.4mm) | PTH | Round |
| ⊠ | 13 | 63mil (1.6mm) | PTH | Round |
| □ | 4 | 150mil (3.81mm) | PTH | Round |
| 450 Total | | | | |

2500.00

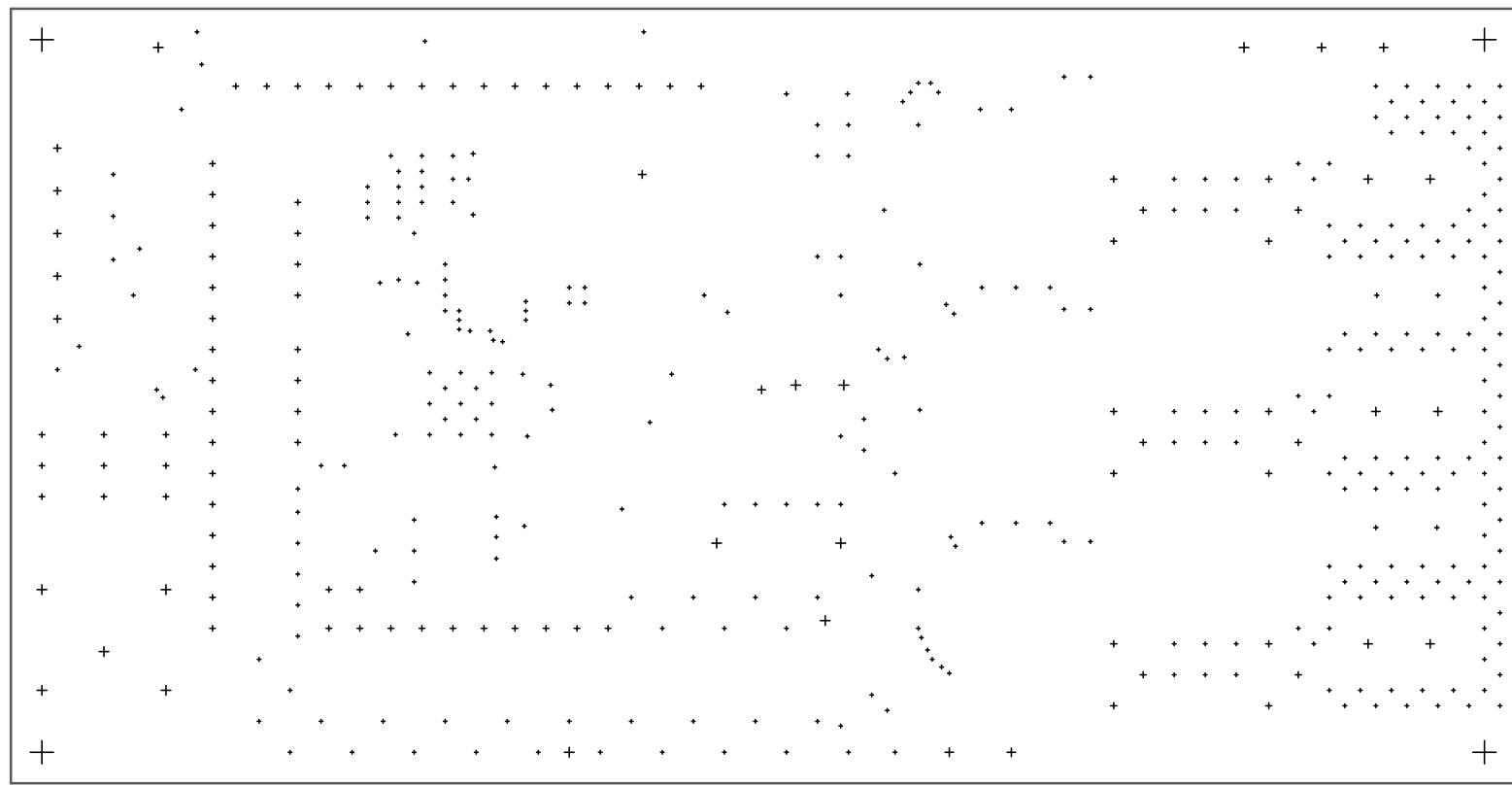

4850.00